


CKG1/CKP1 Series ø40, ø50, ø63

Construction

CKG1□40, 50, 63 Built-in standard magnet type/With magnetic field resistant auto switch

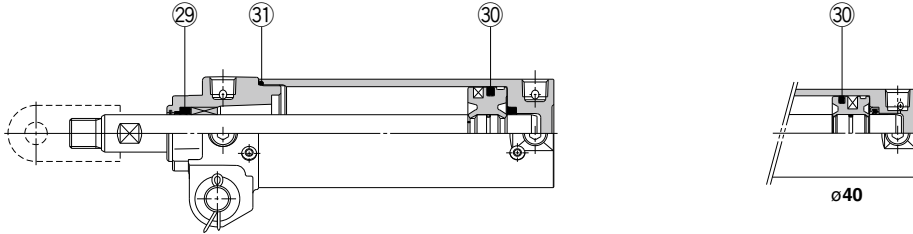

* The numbers correspond with those in the "Construction" of the CKG1 series in the Best Pneumatics catalog.

Seal Kit List

No.	Description	Material	Note
29	Rod seal	NBR	
30	Piston seal		
31	Tube gasket		


Replacement Parts: Seal Kit

Bore size (mm)	Part no.	Contents
40	CK1A40-PS	Set of nos. 29, 30, 31
50	CK1A50-PS	
63	CK1A63-PS	

Note) Since the seal kit does not come with a grease pack, it should be ordered separately.

Grease pack part no.: GR-S-010 (compatible with all sizes)

CKP1□40, 50, 63 Built-in strong magnet type/With magnetic field resistant auto switch

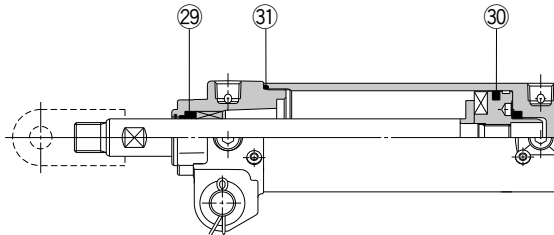

* The numbers correspond with those in the "Construction" of the CKP1 series in the Best Pneumatics catalog.

Seal Kit List

No.	Description	Material	Note
29	Rod seal	NBR	
30	Piston seal		
31	Tube gasket		

Replacement Parts: Seal Kit

Bore size (mm)	Part no.	Contents
40	CK1A40-PS	Set of nos. 29, 30, 31
50	CK1A50-PS	
63	CK1A63-PS	

Note) Since the seal kit does not come with a grease pack, it should be ordered separately.

Grease pack part no.: GR-S-010 (compatible with all sizes)

Actuators

Modular F.R.L.
Pressure Control Equipment

Air Preparation
Equipment

Industrial Filters

Replacement
Procedure

Actuators

Modular F.R.L.
Pressure Control Equipment

Industrial Filters