



Contact our sales office regarding a delivery date or a price since this is a special model.

SP133X-006E
P: RT

SMC P.G.Information (Specialized Product)

SMC CORPORATION
4-14-1, SOTO-KANDA,
CHIYODA-KU,
TOKYO 101-0021, JAPAN
URL: <http://www.smcworld.com>

S Couplers / KK130※-X206

■Features

Hose size 9x15 mm (I.D. /O.D.) applicable to nut coupler fitting models for fiber reinforced urethane hose



Model	Specifications
KK130P-X206 KK130S-X206	Hose I.D./O.D. (mm) 9 / 15

■Specifications

Fluid	Air
Operating pressure range	0 to 1.5MPa
Ambient and fluid temperature	-20 to 80°C (No freezing)
Proof pressure	2.0MPa

* The specifications are based on the coupler. Please use it while following the specifications of the hose in use.

■How to Order and Dimensions (mm)

◇KK130※-X206

KK130 ※ - 90 N - X206

Socket/Plug

Symbol	Type
P	Plug
S	Socket

Connection type


Symbol	Type
N	With nut fitting

Applicable hose


Symbol	I.D./O.D. [mm]
90	9 / 15

■How to Order and Dimensions (mm)

◇KK130P-90N-X206

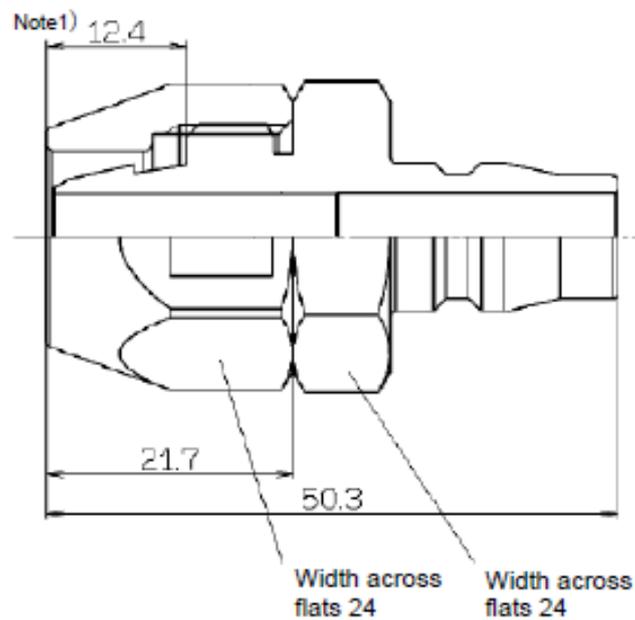

◇KK130S-90N-X206

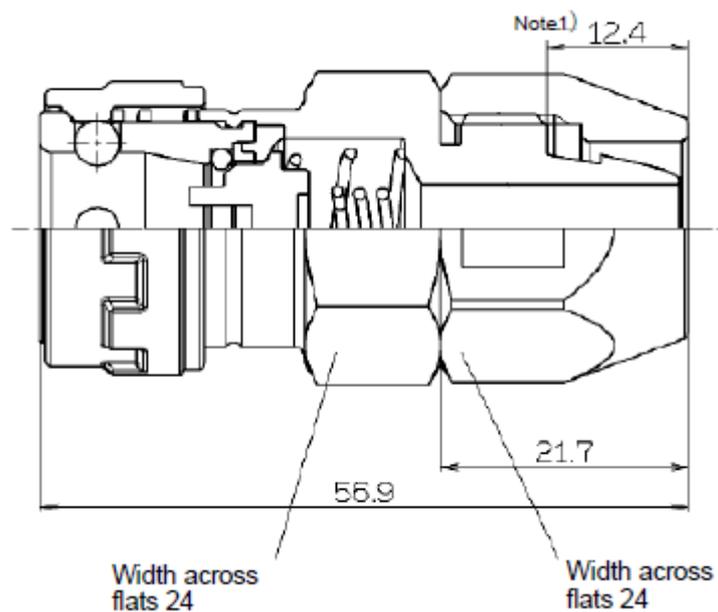

Note 1: Reference dimensions for insertion of applicable hose.



Caution To ensure the safest possible operation of this product, please be sure to read thoroughly the "Safety Instructions" in our "Best Pneumatics" catalog before use.