




## 36 mm<sup>2</sup> square panel mount adapter for digital pressure switch

SMC CORPORATION  
4-14-1, SOTO-KANDA,  
CHIYODA-KU,  
TOKYO 101-0021, JAPAN  
URL: <http://www.smcworld.com>

### ■ Feature :


A Z/ISE30A series digital pressure switch can be mounted to a 36 mm<sup>2</sup> square panel.

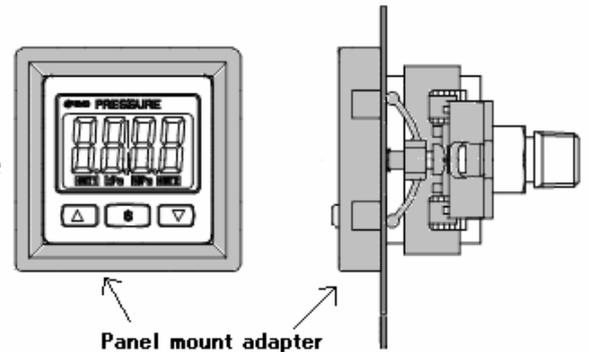

Example) Z/ISE30A can be mounted to a panel that had the Z/ISE40 or Z/ISE4 series mounted.

\* It is possible to mount the PSE300 series (Connector type).

◆ Front protective cover is available.

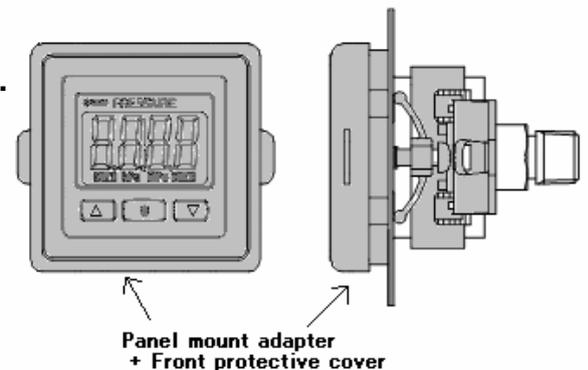

### ■ How to order

Description	Model	Remarks
36 mm <sup>2</sup> square panel mount adapter	ZS-38-E	With 2 mounting screws (M3×8L)
36 mm <sup>2</sup> square panel mount adapter + 36 mm <sup>2</sup> square front protective cover	ZS-38-F	With 2 mounting screws (M3×8L)
36 mm <sup>2</sup> front protective cover <sup>Note)</sup>	ZS-24-03	

Note) A 36 mm<sup>2</sup> square panel mount adapter is required to mount a 36 mm<sup>2</sup> square front protective cover.


Please note that panel mounting is impossible with only a front protective cover.

## ■ Mounting by panel mount adapter :

Secure the panel mount adapter to the pressure switch with the set screws M3 × 8L (2 pieces).


### 36 mm<sup>2</sup> square panel mount adapter

(Model: ZS-38-E)

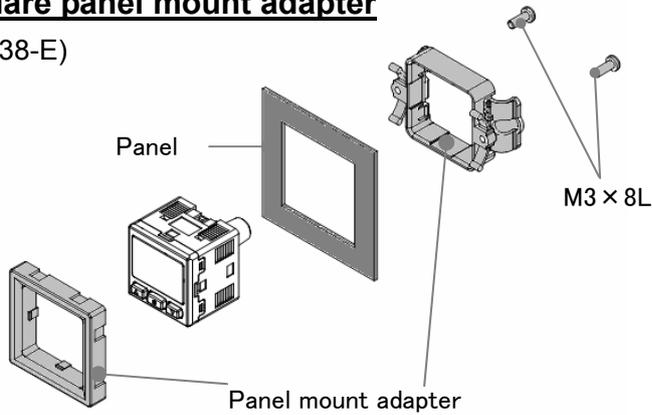

### 36 mm<sup>2</sup> square panel mount adapter + Front protective cover


(Model: ZS-38-F)

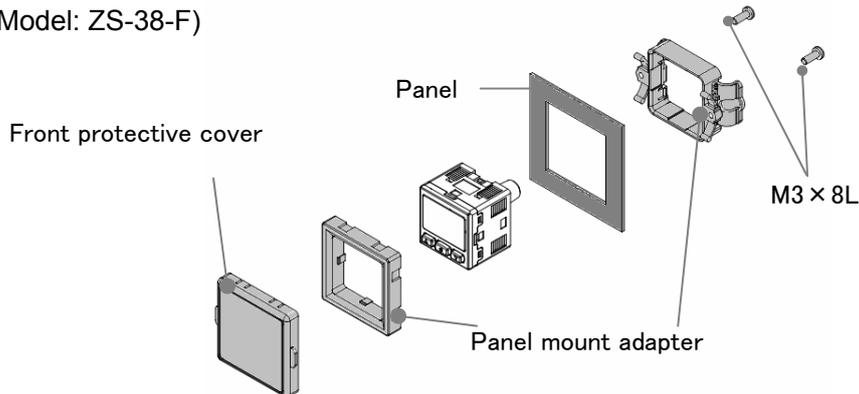

※The panel mount adapter and the front protective cover can be rotated by 90 degrees for mounting.

#### **Notice when removing the switch**

- The Pressure switch with the panel mount adapter can be removed from equipment by widening the hook of the switch as following after removing two screws. The Pressure switch and panel mount adapter may be damaged.

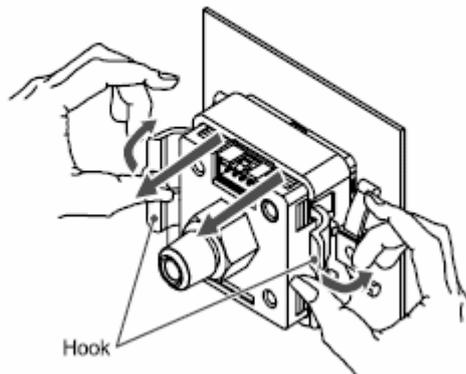


## ■Dimensions : mm

### **36 mm<sup>2</sup> square panel mount adapter**

(Model.: ZS-38-E)

Digital Pressure Switch: ZSE30A(F)/ISE30A-01-\*

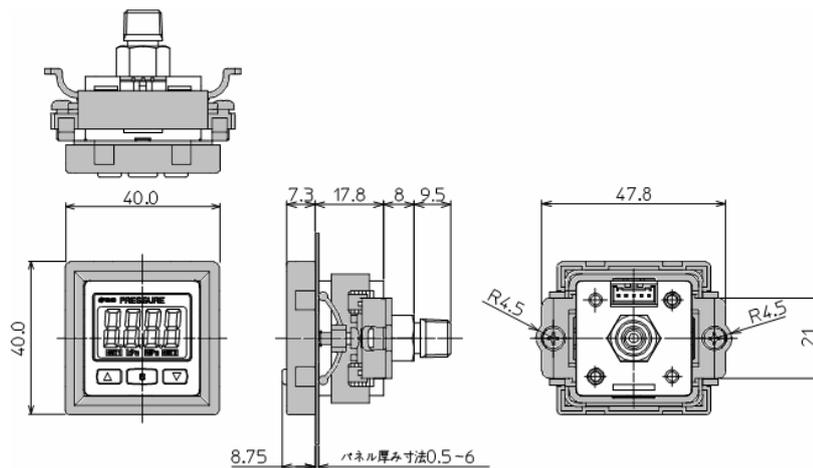


※Panel mount adapter can be rotated by 90 degrees for mounting.

### **36 mm<sup>2</sup> square panel mount adapter + Front protective cover**

(Model.: ZS-38-F)

Digital Pressure Switch: ZSE30A(F)/ISE30A-01-\*

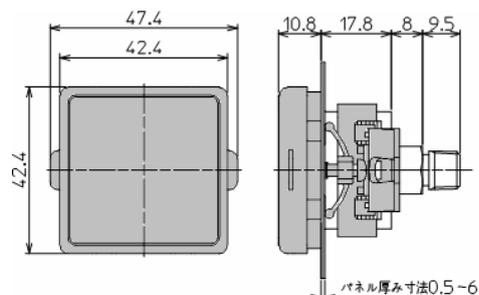

※The panel mount adapter and the front protective cover can be rotated by 90 degrees for mounting.


## ■ Panel cutout dimension: mm

**When ZS-38-E (36 mm<sup>2</sup> square panel mount adapter only) is used**


Single pressure switch

Two or more in a row

n: Number of the pressure switches

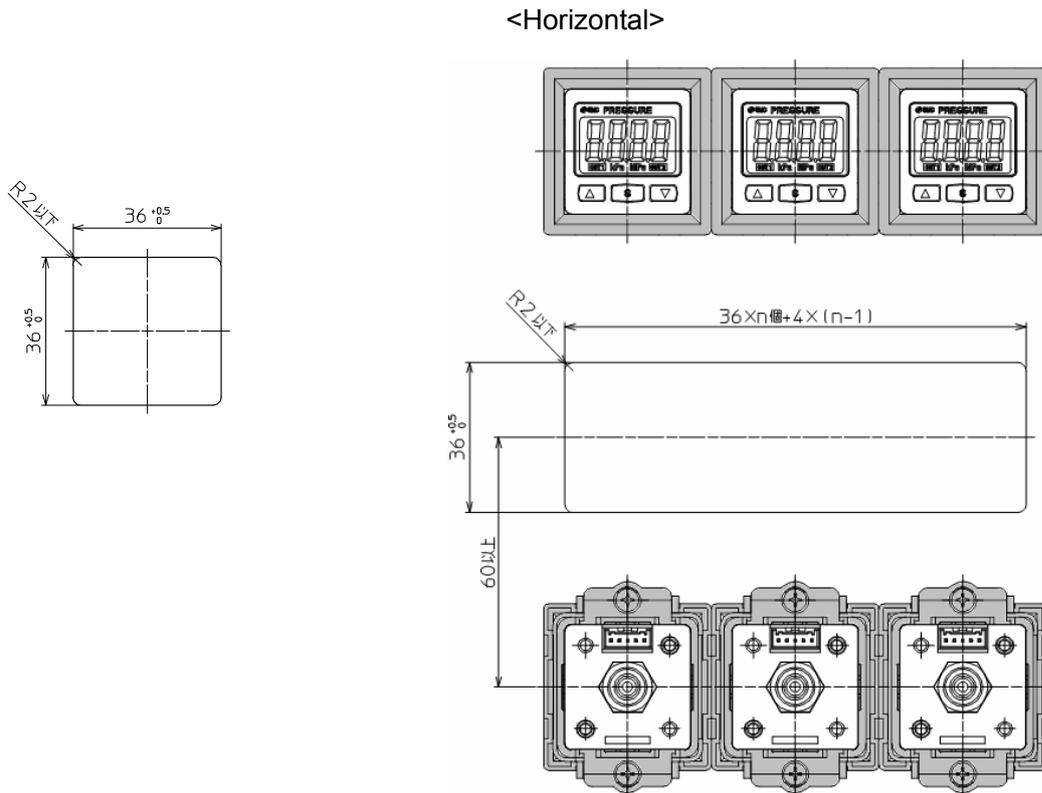


<Vertical>

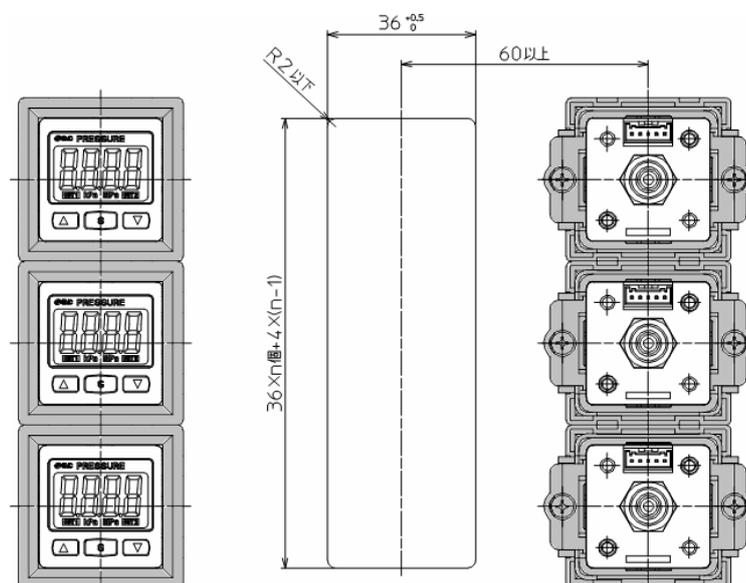

**When ZS-38-F(36 mm<sup>2</sup> square panel mount adapter + 36 mm<sup>2</sup> square front protective cover) is used**

Note) When a front protective cover is used, side-by-side contact mounting is not possible.

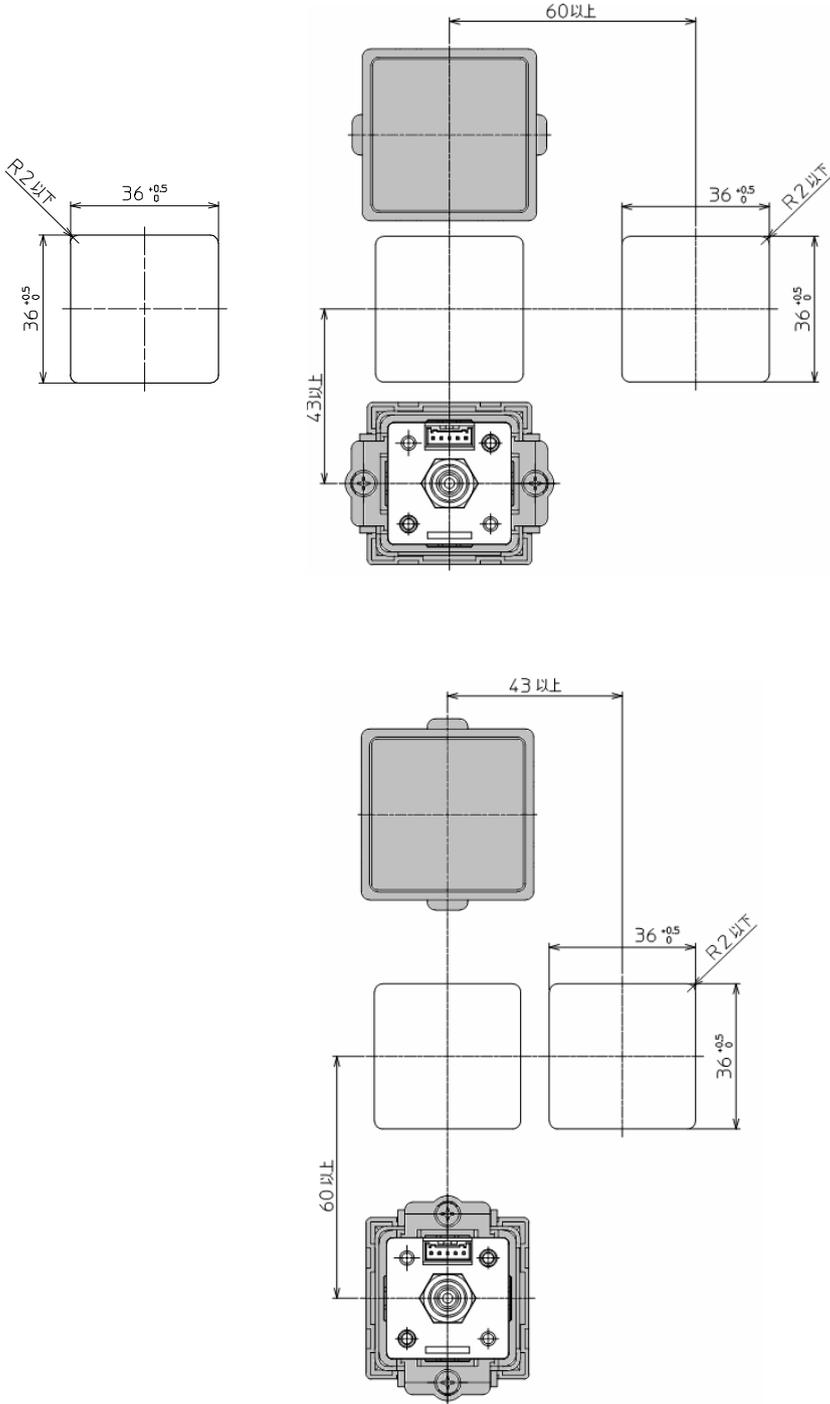

**Caution** To ensure the safest possible operation of this product, please be sure to read thoroughly the "Safety Instructions" in our "Best Pneumatics" catalog before use.