


# Lock Unit

# MWB-UT-X3075

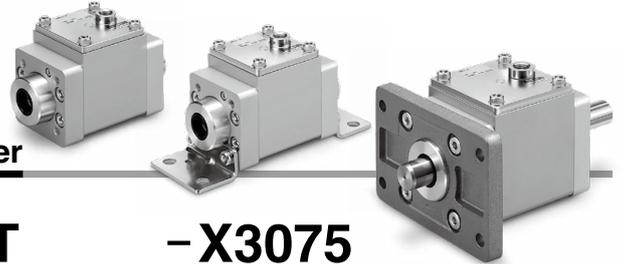

## How to Order

**MWB B 40 [ ] - UT - X3075**  
**With rod MWB B 40 [ ] - UT - 500 - X3075**

### Mounting

<b>B</b>	Basic
<b>L</b>	Axial foot
<b>F</b>	Flange

\* Mounting bracket is shipped together with the product.

### Model

Model	Applicable rod size
<b>32</b>	12 mm
<b>40</b>	16 mm
<b>50</b>	20 mm
<b>63</b>	20 mm
<b>80</b>	25 mm
<b>100</b>	30 mm


### Port thread type

<b>Nil</b>	Rc
<b>TN</b>	NPT
<b>TF</b>	G

### Rod length [mm]

Nil		Without accessory rod	
Min. length	Max. length	Applicable model	Note
250	2500	<b>32</b>	Can be manufactured in increments of 1 mm up to the maximum length.
300		<b>40</b>	
		<b>50</b>	
		<b>63</b>	
		<b>80</b>	
		<b>100</b>	

\* The rod length indicates the overall length of the rod.

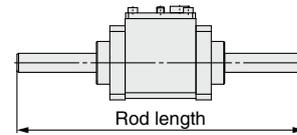

\* Rod is shipped together with the product.

**Table 1**

Bore size (mm)	Usage	
	Lock	Brake
<b>32</b>	OK	OK
<b>40</b>	OK	OK
<b>50</b>	OK	OK
<b>63</b>	OK	OK
<b>80</b>	OK	OK
<b>100</b>	OK	OK

This product provides braking function and locking function.

These functions are defined as follows:

- Braking means to stop a moving object (intermediate stop or emergency stop).
- Locking means to retain a stationary object in place (drop prevention or holding position).

SMC validation products have been validated based on ISO 13849-2: 2012 Annex A.