



加熱能力

HRS⁰¹²₀₁₈-A-W-10 (単相AC100/115V)

[50Hz]

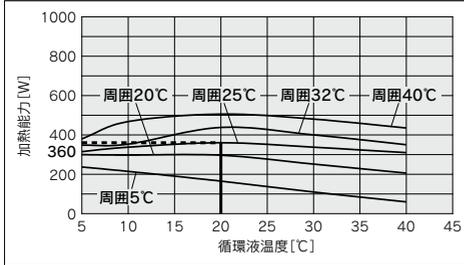


[60Hz]

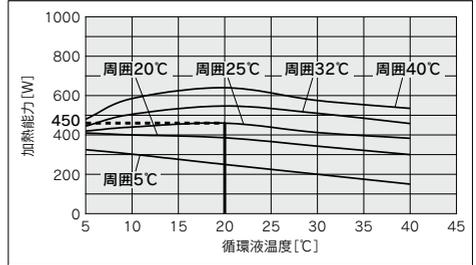


HRS⁰¹²₀₁₈-A-W-20 (単相AC200~230V)

[50Hz]

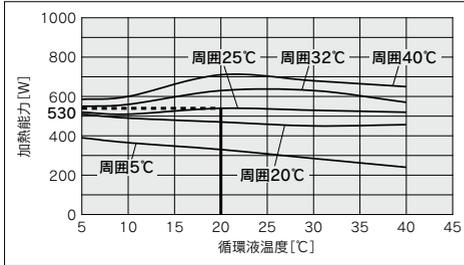


[60Hz]

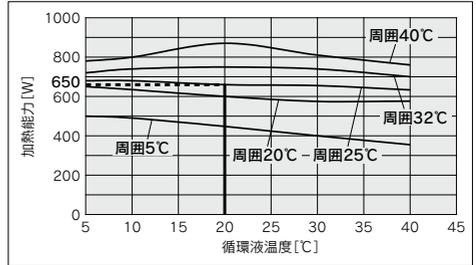


HRS030-A-20 (単相AC200~230V)

[50Hz]

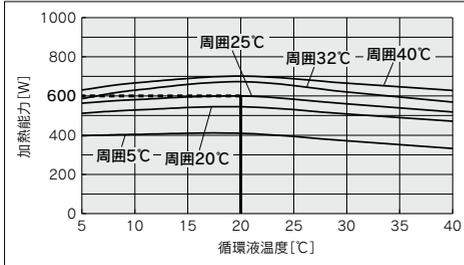


[60Hz]

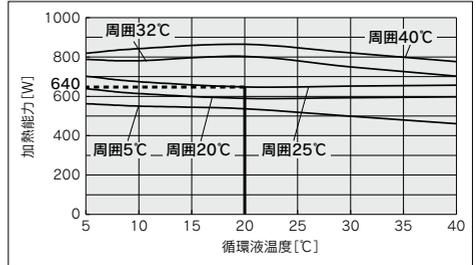


HRS030-W-20 (単相AC200~230V)

[50Hz]

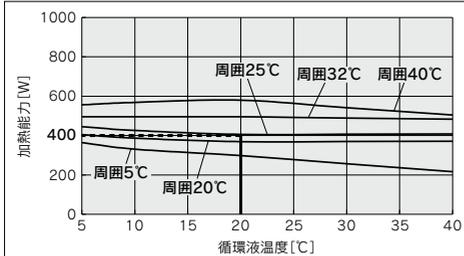


[60Hz]

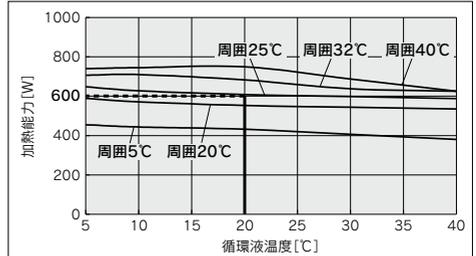


加熱能力


HRS050-A-20 (単相AC200~230V) [50Hz]

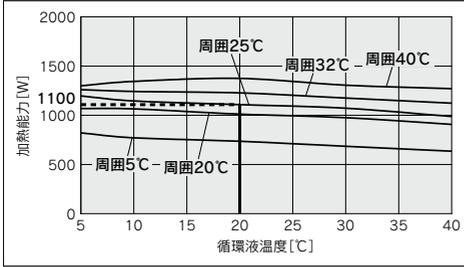


[60Hz]

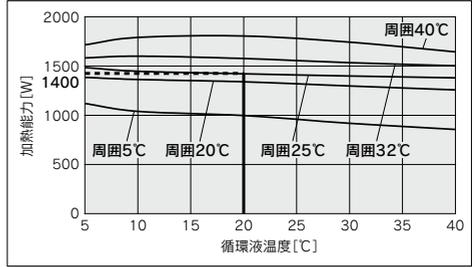


HRS050-W-20 (単相AC200~230V) [50Hz]

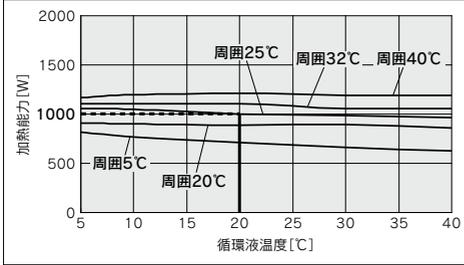


[60Hz]

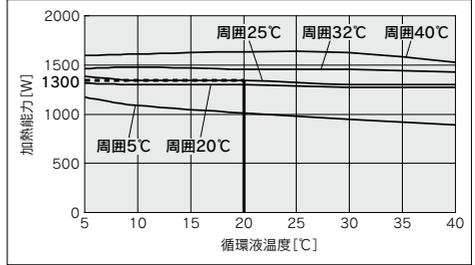


HRS060-A-20 (単相AC200~230V) [50Hz]

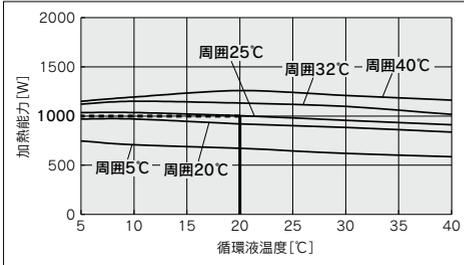

[60Hz]

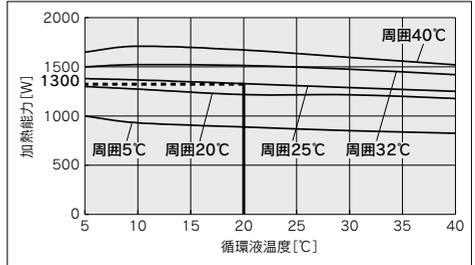

HRS060-W-20 (単相AC200~230V) [50Hz]

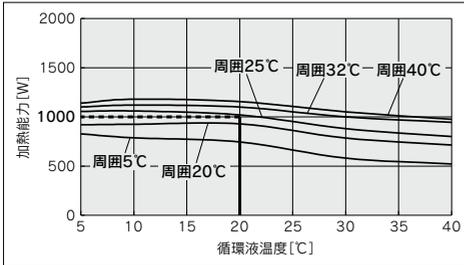

[60Hz]

