

Made to Order Common Specifications: -XB10A: Intermediate Stroke (Spacer-installed type)



6 Intermediate Stroke (Spacer-installed type)

Symbol
-XB10A

A spacer is installed on the exclusive body (● indication). The overall length is shorter than that of the spacer-installed type 1. The ◎ indicates the selectable stroke range. (Strokes with the ● indication are not selectable.) The — indicates strokes supported by the spacer-installed type 1.

Bore size [mm]	Stroke range	Stroke											
		55	60	65	70	75	80	85	90	95			
32 to 100	51 to 94	◎	●	◎	●	◎	●	◎	●	◎	●	◎	●

Ordering example


Part no.	CQ2B50-57DZ-XB10A	
Description	<ul style="list-style-type: none"> ● Uses an exclusive tube (60 mm stroke) in "3". ● Makes 57 mm stroke with 3 mm spacer inside. ● The B dimension is 100.5 mm. B = 40.5 + 60 	

Specifications: Same as standard type

How to Order Q2 Standard model no. — XB10 A
 Intermediate stroke ●
 Spacer-installed type ●

Dimensions: CQ2 Series (Dimensions other than those below are the same as those of the standard type.)

Double acting, Single rod

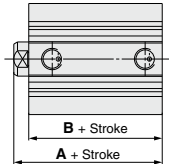

Symbol Stroke	A																B							
	51 to 54	56 to 59	61 to 64	66 to 69	76 to 79	81 to 84	86 to 89	91 to 94	51 to 54	56 to 59	61 to 64	66 to 69	76 to 79	81 to 84	86 to 89	91 to 94								
Bore size																	(mm)							
32	95	100	105	110	120	125	130	135	88	93	98	103	113	118	123	128								
40	101.5	106.5	111.5	116.5	126.5	131.5	136.5	141.5	94.5	99.5	104.5	109.5	119.5	124.5	129.5	134.5								
50	103.5	108.5	113.5	118.5	128.5	133.5	138.5	143.5	95.5	100.5	105.5	110.5	120.5	125.5	130.5	135.5								
63	109	114	119	124	134	139	144	149	101	106	111	116	126	131	136	141								
80	118.5	123.5	128.5	133.5	143.5	148.5	153.5	158.5	108.5	113.5	118.5	123.5	133.5	138.5	143.5	148.5								
100	130	135	140	145	155	160	165	170	118	123	128	133	143	148	153	158								