

# Made to Order Common Specifications: -XC26: With Split Pins for Double Clevis Pin and Double Knuckle Joint Pin and Flat Washers



## 32 With Split Pins for Double Clevis Pin/Double Knuckle Joint Pin and Flat Washers **-XC26**

Flat washer is added for the double clevis (one of the mounting types) or double knuckle joint (one of the accessories).

### Applicable Series


Series	Description	Model	Action	Note	Vol. no. (for std model)
MB	Air cylinder	MB	Double acting, Single rod	ø125 only	②-1 From P. 392
MB1	Air cylinder	MB1	Double acting, Single rod	ø125 only	②-1 From P. 440
		MB1W	Double acting, Double rod	ø125 only	
CS2	Standard type Smooth cylinder	CS2-Z	Double acting, Single rod		②-1 From P. 568
		CS2Y-Z	Double acting, Single rod		

### Specifications

<b>Mounting type</b>	Only double clevis type (D), Double knuckle joint
<b>Changed parts</b>	Clevis pin, knuckle joint pin, flat washer
<b>Specifications other than above</b>	Same as standard type

### Dimensions (Dimensions other than below are the same as standard type.)


#### Double clevis

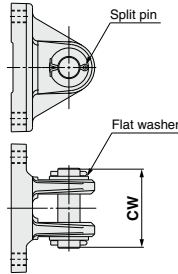

- \* For mounting bracket, split pin, clevis pin and flat washer are shipped together, (but not assembled).
- \* Mounting method is the same as standard type.

Bore size (mm)	CW
ø125	90
ø140	104
ø160	113

#### Double knuckle joint

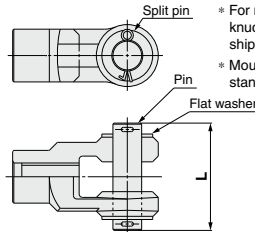


- \* For mounting bracket, split pin, knuckle joint pin and flat washer are shipped together, (but not assembled).
- \* Mounting method is the same as standard type.




Bore size (mm)	L
ø125	90
ø140	104
ø160	113

### How to Order

#### • Product

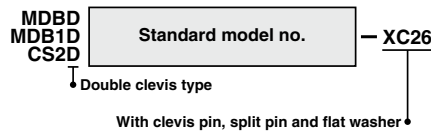

#### • Parts assembly

  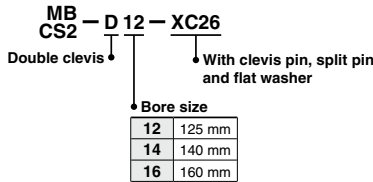

# Made to Order Common Specifications: -XC26: With Split Pins for Double Clevis Pin and Double Knuckle Joint Pin and Flat Washers



## 32 With Split Pins for Double Clevis Pin/Double Knuckle Joint Pin and Flat Washers -XC26

A pin for double clevis (one of the mounting types) or double knuckle joint (one of the accessories) has been changed for a split pin, and split pins and flat washers have been added.

### Applicable Series


Series	Model	Action	Vol. no. (for std model)
CQS	Standard type	CQS	Double acting, Single rod Single acting Spring return/extended
	Long stroke	CQS	Double acting, Single rod
	Non-rotating rod type	CQSK	Double acting, Single rod
	Anti-lateral load type	CQS□S	Double acting, Single rod
CQ2	Standard type	CQ2-Z	Double acting, Single rod Single acting Spring return/extended
	Long stroke	CQ2-Z	Double acting, Single rod
	Non-rotating rod type	CQ2K-Z	Double acting, Single rod
	Anti-lateral load type	CQ2□S-Z	Double acting, Single rod
	With end lock	CBQ2	Double acting, Single rod
	Magnetic field resistant	CDQ2□P	Double acting, Single rod
	Copper-free compact	20-CQ2-Z	Double acting, Single rod Single acting Spring return/extended
	Copper-free long stroke	20-CQ2□-Z	Double acting, Single rod
	Copper-free anti-lateral load	20-CQ2□S-Z	Double acting, Single rod

### Specifications

Mounting	Double clevis (D) only
Changed parts	Clevis pin/Knuckle pin, Split pin, Flat washer
Specifications other than above	Same as standard


### Dimensions: Same as Standard

#### Double clevis

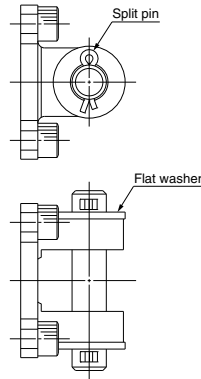


### How to Order
 
#### • Product





#### • Parts assembly

 

#### • Bore size


012	12 mm
016	16 mm
020	20 mm
025	25 mm
032	32 mm
040	40 mm
050	50 mm
063	63 mm
080	80 mm
100	100 mm

  \* For the CQS, only bore sizes 012 to 025 are selectable.



\* For mounting bracket, split pins, clevis pin and flat washers are shipped together, (but not assembled).  
\* Mounting method is the same as standard.

#### Double knuckle joint

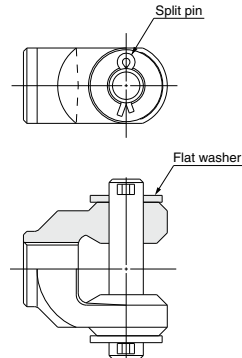

\* For mounting bracket, split pins, knuckle pin and flat washers are shipped together, (but not assembled).  
\* Mounting method is the same as standard.